




## Cable Control

Innovation Sheet

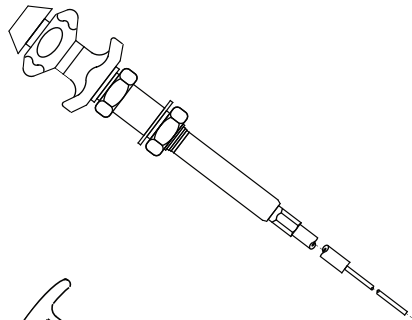


### Vernier Controls

**Catalog Number: 8374**

New advanced styling. Meets or exceeds OEM specifications. Non-Corrosive aircraft aluminum body and stainless steel shaft assures 400 hour salt spray test without corrosion.

A direct replacement for most "Remote Throttle Controls"; Mack Truck 21QB-180 Series, Kenworth K068B Series, Peterbilt 05-1462 Series, Volvo-White 13401 Series, I.H. 34084 Series, Muncie COCL Series and BPC VCG Series. Also replaces most Garage and Service Station Wreckers remote control throttles; Earnest Holmes, Dover, etc.

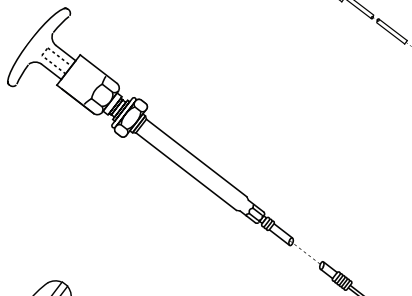


### Turn-To-Lock Controls (T-Locking)

**Catalog Number: 8370, 8371**

New positive action control for small to mid-size engine throttles, governors, chokes, fuel shut-offs and more.

Aluminum body assures rust free performance. Patented Acetal Locking bushing guarantees never before possible settings with one third operator effort. Replaces Muncie COCL Series and BPC R09 Series.

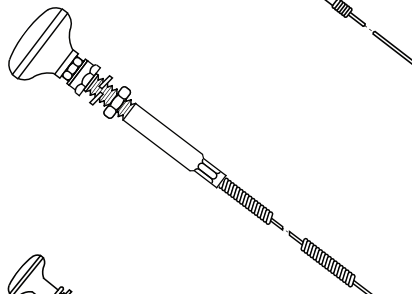


### Power Take Off Controls (Ball Knob)

**Catalog Numbers: 8372, 8373**

Utility grade as exact replacement for most PTO. Controls.


Features 2" Round Knobs, Galvanized Steel, vinyl covered casing and steel inner wire. All PTO. Controls meet or exceed OEM specifications. Replaces BPC R-38DS, R04, R38, R38D Series and Muncie COKB Series.

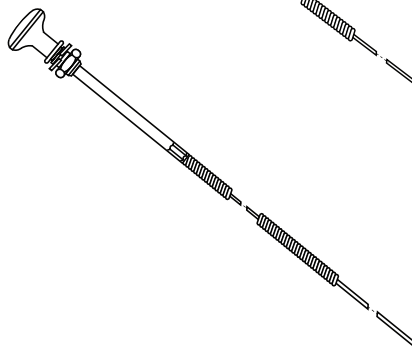

### Utility Light Load Controls (Dash)


**Catalog Numbers: 8375, 8376, 8377, 8378**

Universal light load Choke, Fuel-Shutoff, Throttle, Hood, Trunk and more! Controls are designed for most engine applications. Stainless steel innerwire resists corrosion and assures trouble free operation. Vinyl coated.

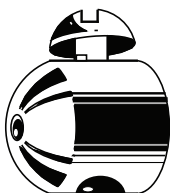

### Throttle Stop

**Catalog Number : 1548**

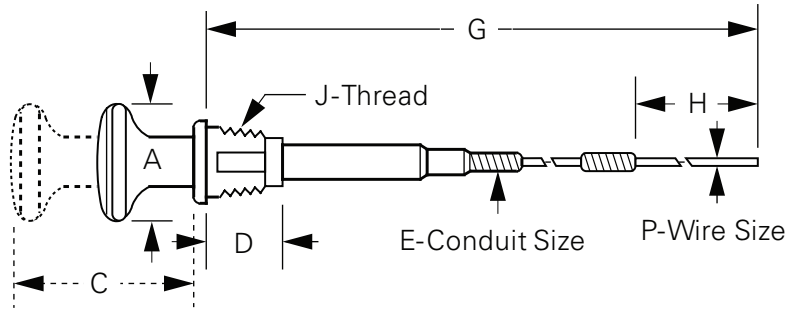

**SPECIFICATION CHART ON "PUSH-PULL" CONTROLS**

Description	Dash				T-Hood	T-Locking		PTO Control		Vernier	Deluxe PTO Control	
	8375	8376	8377	8378		8367	8370	8371	8372		8373	8374
Catalog Number	8375	8376	8377	8378	8367	8370	8371	8372	8373	8374	106370	106470
Length of "G"	84"	84"	84"	60"	180"	126"	186"	81"	165"	120"	192"	300"
Length of "H"	9-3/8"	9-3/8"	9-3/8"	7"	5"	6"	6"	3"	3"	4-1/2"	12"	12"
Knob Type	Round				T-Handle	T-Handle		Round		Round	Round	
Knob Size "A"	1.06"				2"	2"		2"		2"	2"	
Knob Color	Black				Chrome	Chrome		Black		Black	Red	
Knob Material	Plastic				Cast Zinc	Nylon		Plastic		Plastic	Plastic	
Knob Lettering	Choke	Throttle	None	None	None	Lock		None		None	None	
Knob Travel "C"	2-1/2"				2-1/2"	3"		3-1/2"		3-3/8"	4-1/2"	
Thread Size "J"	3/8"-24				3/8"-24"	7/16"-20		7/16"-20		3/4"-16	1/2"-20	
Thread Length "D"	1/2"				1/2"	3/4"		1-5/32"		2-1/2"	1-1/8"	
Conduit Size "E"	3/16"				3/16"	3/16"		1/4"		1/4"	3/8"	
Conduit Material & Style	Galvanized Steel				Steel Vinyl Cover	Galvanised Steel		Galvanised Steel		Galvanised Steel	Galvanised Steel	
	Vinyl	Vinyl	Vinyl	Vinyl		Vinyl Covered		Vinyl Covered		Vinyl Covered	Vinyl Covered	
Wire Size "P"	.054"				.054"	.054"		.088"		.0625"	.088"	

**Eaton**  
 14615 Lone Oak Road  
 Eden Prairie, MN 55344  
 USA  
 Tel: 952 937-9800  
 Fax: 952 974-7722  
 www.hydraulics.eaton.com

**Eaton**  
 20 Rosamond Road  
 Footscray  
 Victoria 3011  
 Australia  
 Tel: (61) 3 9319 8222  
 Fax: (61) 3 9318 5714

**Eaton**  
 Dr.-Reckeweg-Str. 1  
 D-76532 Baden-Baden  
 Germany  
 Tel: (49) 7221 682-0  
 Fax: (49) 7221 682-788

